

TAPE AND REEL INFORMATION

QUADRANT ASSIGNMENTS FOR PIN 1 ORIENTATION IN TAPE

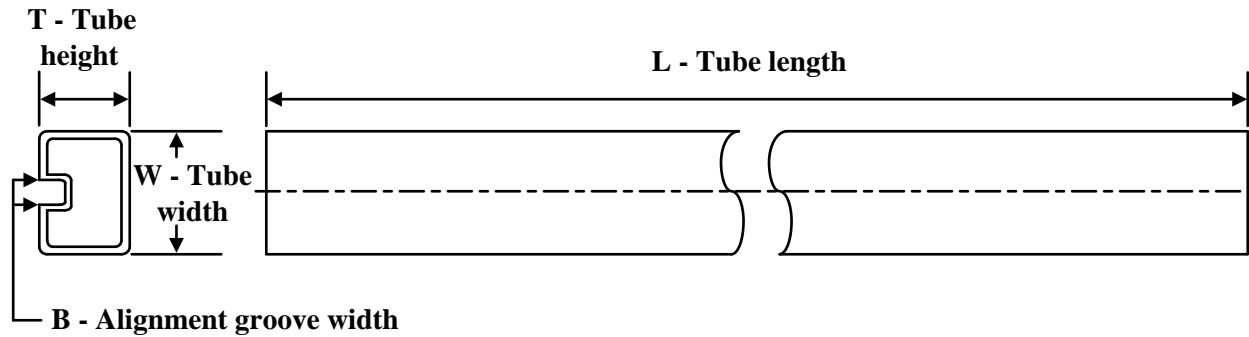

*All dimensions are nominal

Device	Package Type	Package Drawing	Pins	SPQ	Reel Diameter (mm)	Reel Width W1 (mm)	A0 (mm)	B0 (mm)	K0 (mm)	P1 (mm)	W (mm)	Pin1 Quadrant
TPS40210DGQR	HVSSOP	DGQ	10	2500	330.0	12.4	5.25	3.35	1.25	8.0	12.0	Q1
TPS40210DRCR	VSON	DRC	10	3000	330.0	12.4	3.3	3.3	1.1	8.0	12.0	Q2
TPS40210DRCT	VSON	DRC	10	250	180.0	12.4	3.3	3.3	1.1	8.0	12.0	Q2
TPS40210DRCTG4	VSON	DRC	10	250	180.0	12.4	3.3	3.3	1.1	8.0	12.0	Q2
TPS40211DGQR	HVSSOP	DGQ	10	2500	330.0	12.4	5.3	3.4	1.4	8.0	12.0	Q1
TPS40211DRCR	VSON	DRC	10	3000	330.0	12.4	3.3	3.3	1.1	8.0	12.0	Q2
TPS40211DRCT	VSON	DRC	10	250	180.0	12.4	3.3	3.3	1.1	8.0	12.0	Q2

TAPE AND REEL BOX DIMENSIONS


*All dimensions are nominal

Device	Package Type	Package Drawing	Pins	SPQ	Length (mm)	Width (mm)	Height (mm)
TPS40210DGQR	HVSSOP	DGQ	10	2500	366.0	364.0	50.0
TPS40210DRCR	VSON	DRC	10	3000	353.0	353.0	32.0
TPS40210DRCT	VSON	DRC	10	250	213.0	191.0	35.0
TPS40210DRCTG4	VSON	DRC	10	250	213.0	191.0	35.0
TPS40211DGQR	HVSSOP	DGQ	10	2500	364.0	364.0	27.0
TPS40211DRCR	VSON	DRC	10	3000	353.0	353.0	32.0
TPS40211DRCT	VSON	DRC	10	250	213.0	191.0	35.0

TUBE


*All dimensions are nominal

Device	Package Name	Package Type	Pins	SPQ	L (mm)	W (mm)	T (μm)	B (mm)
TPS40210DGQ	DGQ	HVSSOP	10	80	322	6.55	1000	3.01
TPS40210DGQ	DGQ	HVSSOP	10	80	330	6.55	500	2.88
TPS40210DGQ.A	DGQ	HVSSOP	10	80	330	6.55	500	2.88
TPS40210DGQ.A	DGQ	HVSSOP	10	80	322	6.55	1000	3.01
TPS40210DGQG4	DGQ	HVSSOP	10	80	330	6.55	500	2.88
TPS40210DGQG4	DGQ	HVSSOP	10	80	322	6.55	1000	3.01
TPS40211DGQ	DGQ	HVSSOP	10	80	322	6.55	1000	3.01
TPS40211DGQ	DGQ	HVSSOP	10	80	330	6.55	500	2.88
TPS40211DGQ.A	DGQ	HVSSOP	10	80	322	6.55	1000	3.01
TPS40211DGQ.A	DGQ	HVSSOP	10	80	330	6.55	500	2.88