




TUSB522PEVM INT039 Rev B

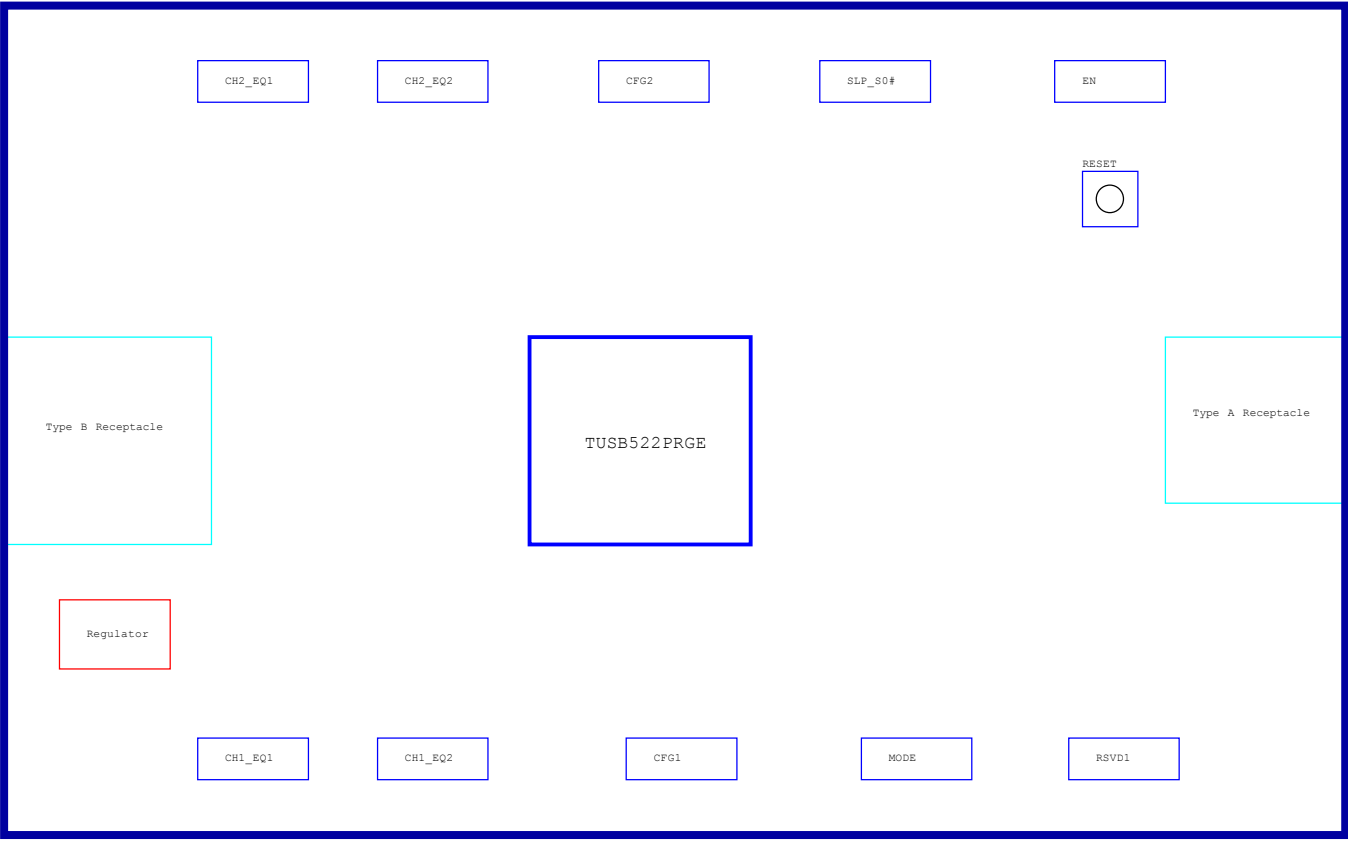


Title			
TUSB522PEVM INT039 Rev B: Block			
Size B	Document Number		Rev B
Date:	Tuesday, April 05, 2016	Sheet 1 of 3	

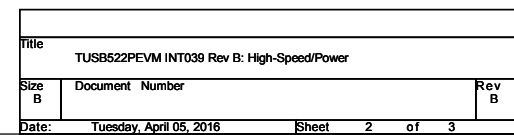


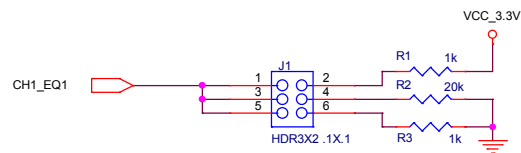


Silkscreen:  
CH1\_EQ1 Selection  
1-2 = 1  
3-4 = R  
5-6 = 0  
NC = F

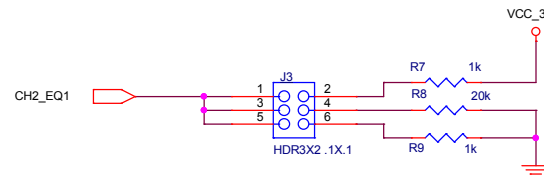


Silkscreen:  
CH2\_EQ1 Selection  
1-2 = 1  
3-4 = R  
5-6 = 0  
NC = F

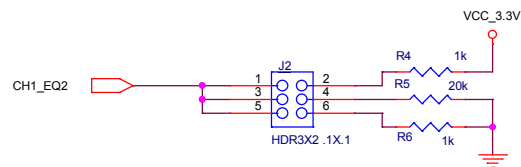


Silkscreen:  
CH1\_EQ2 Selection  
1-2 = 1  
3-4 = R  
5-6 = 0  
NC = F

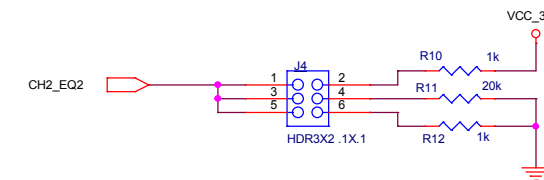


Silkscreen:  
CH2\_EQ2 Selection  
1-2 = 1  
3-4 = R  
5-6 = 0  
NC = F

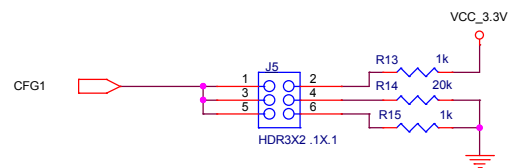


Silkscreen:  
CFG1 Selection  
1-2 = 1  
3-4 = R  
5-6 = 0  
NC = F

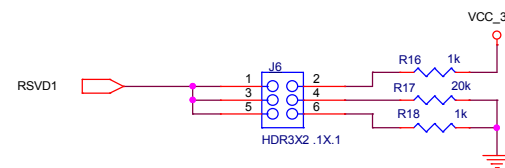


Silkscreen:  
RSVD1 Selection  
1-2 = 1  
3-4 = R  
5-6 = 0  
NC = F

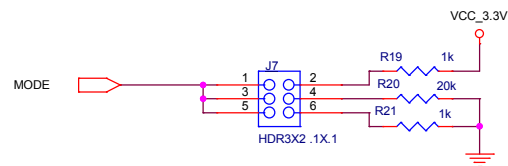


Silkscreen:  
MODE Selection  
1-2 = 1  
3-4 = R  
5-6 = 0  
NC = F

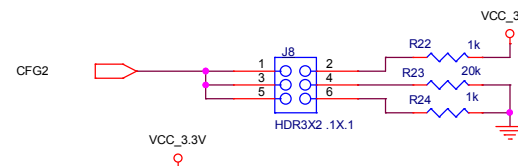

 Silkscreen:  
CFG2 Selection  
1-2 = 1  
3-4 = R  
5-6 = 0  
NC = F



Silkscreen:  
SLP\_S0#

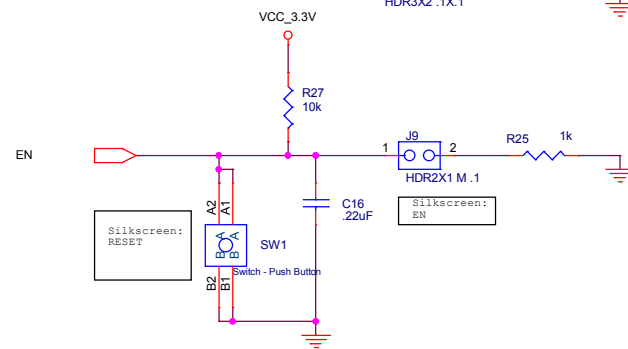

Silkscreen:  
RESET

Silkscreen:  
EN

Title		
TUSBS22PEVM INT039 Rev B: CONFIG		
Size B	Document Number	Rev B
Date:	Monday, April 11, 2016	Sheet 3 of 3