




Top Layer





Bottom Layer

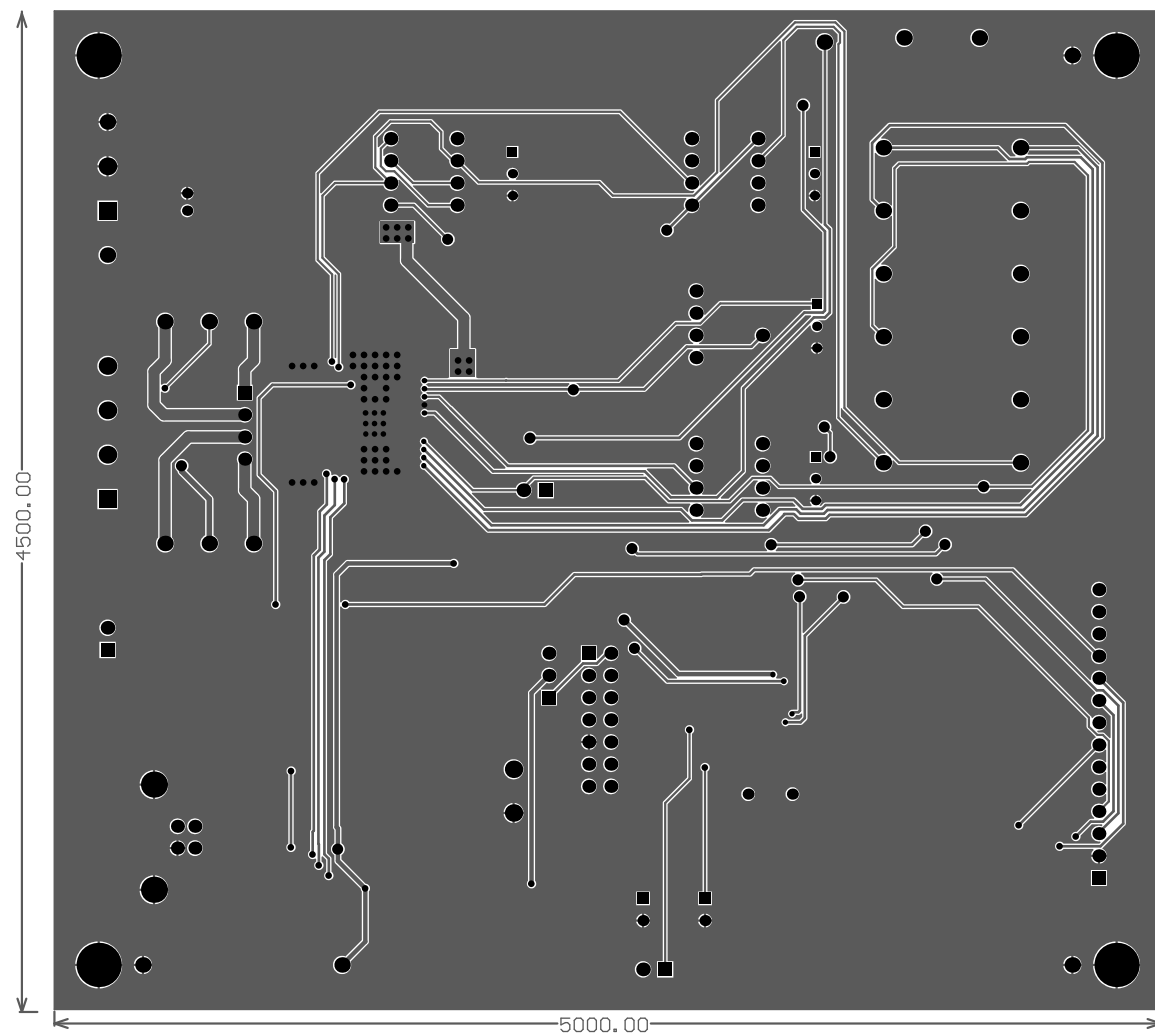

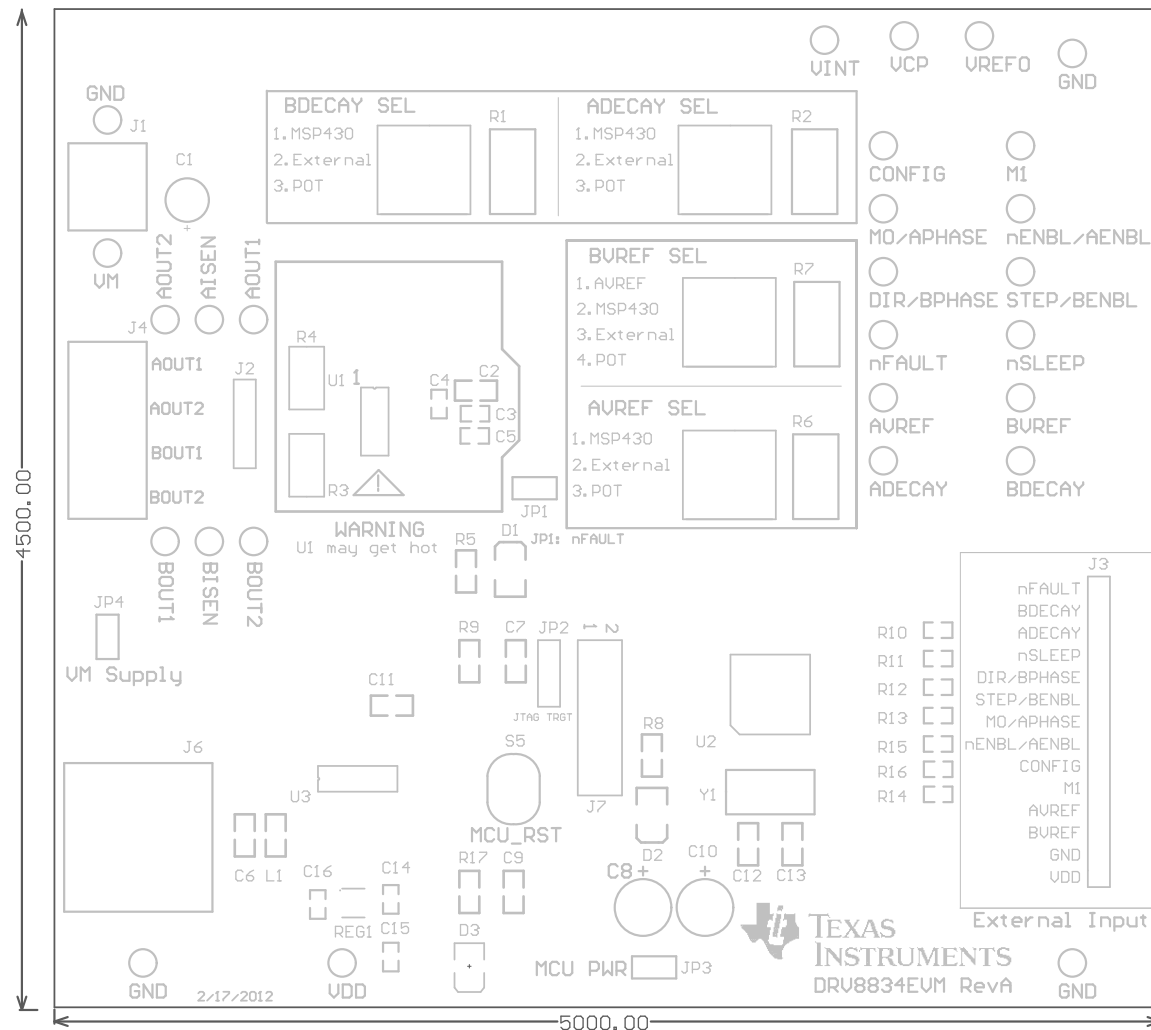

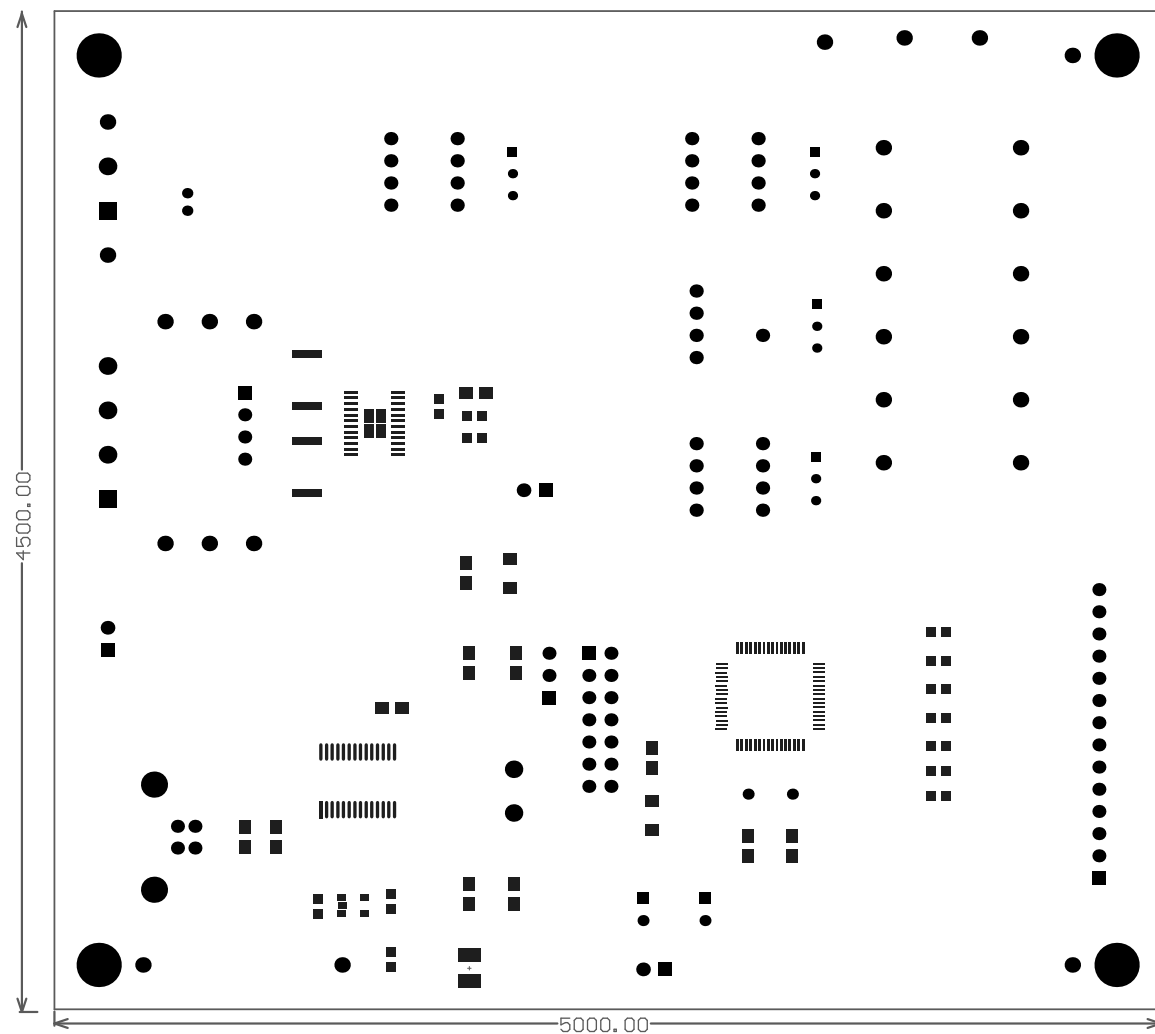

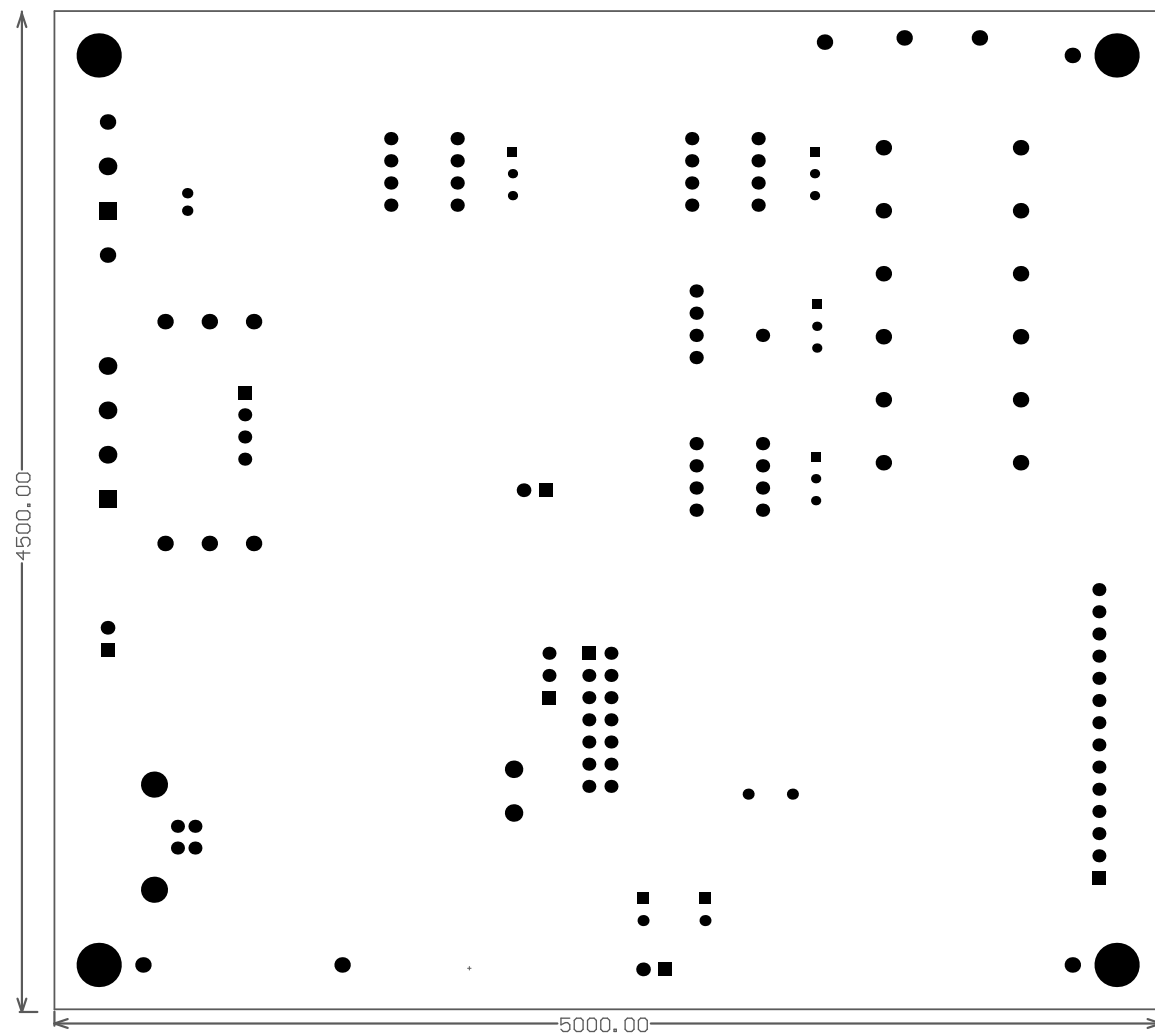

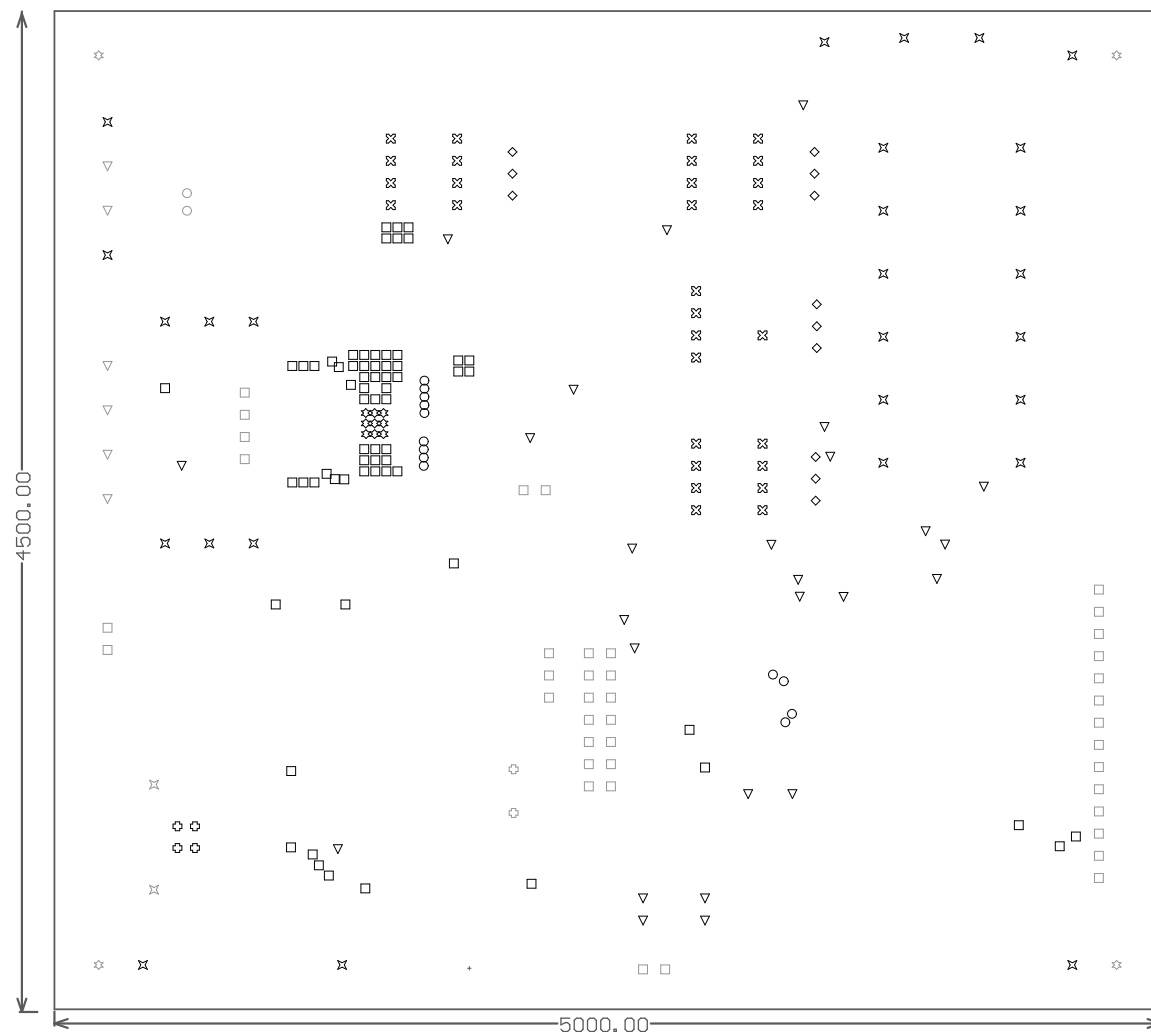

Symbol	Hit Count	Tool Size	Plated	Hole Type
☆	9	12mil (0.3048mm)	PTH	Round
○	13	15mil (0.381mm)	PTH	Round
□	67	16mil (0.4064mm)	PTH	Round
○	2	27.559mil (0.7mm)	PTH	Round
▽	26	28mil (0.7112mm)	PTH	Round
◇	12	29.528mil (0.75mm)	PTH	Round
□	41	35.433mil (0.9mm)	PTH	Round
○	4	36.614mil (0.93mm)	PTH	Round
○	2	39.37mil (1mm)	PTH	Round
⊗	29	40mil (1.016mm)	PTH	Round
▽	6	45mil (1.143mm)	PTH	Round
⊗	27	52mil (1.3208mm)	PTH	Round
⊗	2	90.551mil (2.3mm)	PTH	Round
☆	4	150mil (3.81mm)	PTH	Round
244 Total				

