

**TAPE AND REEL INFORMATION**

**QUADRANT ASSIGNMENTS FOR PIN 1 ORIENTATION IN TAPE**


\*All dimensions are nominal


| Device         | Package Type | Package Drawing | Pins | SPQ  | Reel Diameter (mm) | Reel Width W1 (mm) | A0 (mm) | B0 (mm) | K0 (mm) | P1 (mm) | W (mm) | Pin1 Quadrant |
|----------------|--------------|-----------------|------|------|--------------------|--------------------|---------|---------|---------|---------|--------|---------------|
| DAC3482IRKDR   | WQFN-MR      | RKD             | 88   | 2000 | 330.0              | 16.4               | 9.3     | 9.3     | 1.5     | 12.0    | 16.0   | Q2            |
| DAC3482IRKDRG4 | WQFN-MR      | RKD             | 88   | 2000 | 330.0              | 16.4               | 9.3     | 9.3     | 1.5     | 12.0    | 16.0   | Q2            |
| DAC3482IRKDT   | WQFN-MR      | RKD             | 88   | 250  | 330.0              | 16.4               | 9.3     | 9.3     | 1.5     | 12.0    | 16.0   | Q2            |
| DAC3482IZAYR   | NFBGA        | ZAY             | 196  | 1000 | 330.0              | 24.4               | 12.3    | 12.3    | 2.3     | 16.0    | 24.0   | Q1            |

**TAPE AND REEL BOX DIMENSIONS**


\*All dimensions are nominal

| Device         | Package Type | Package Drawing | Pins | SPQ  | Length (mm) | Width (mm) | Height (mm) |
|----------------|--------------|-----------------|------|------|-------------|------------|-------------|
| DAC3482IRKDR   | WQFN-MR      | RKD             | 88   | 2000 | 336.6       | 336.6      | 28.6        |
| DAC3482IRKDRG4 | WQFN-MR      | RKD             | 88   | 2000 | 336.6       | 336.6      | 28.6        |
| DAC3482IRKDT   | WQFN-MR      | RKD             | 88   | 250  | 367.0       | 367.0      | 38.0        |
| DAC3482IZAYR   | NFBGA        | ZAY             | 196  | 1000 | 350.0       | 350.0      | 43.0        |

**TRAY**

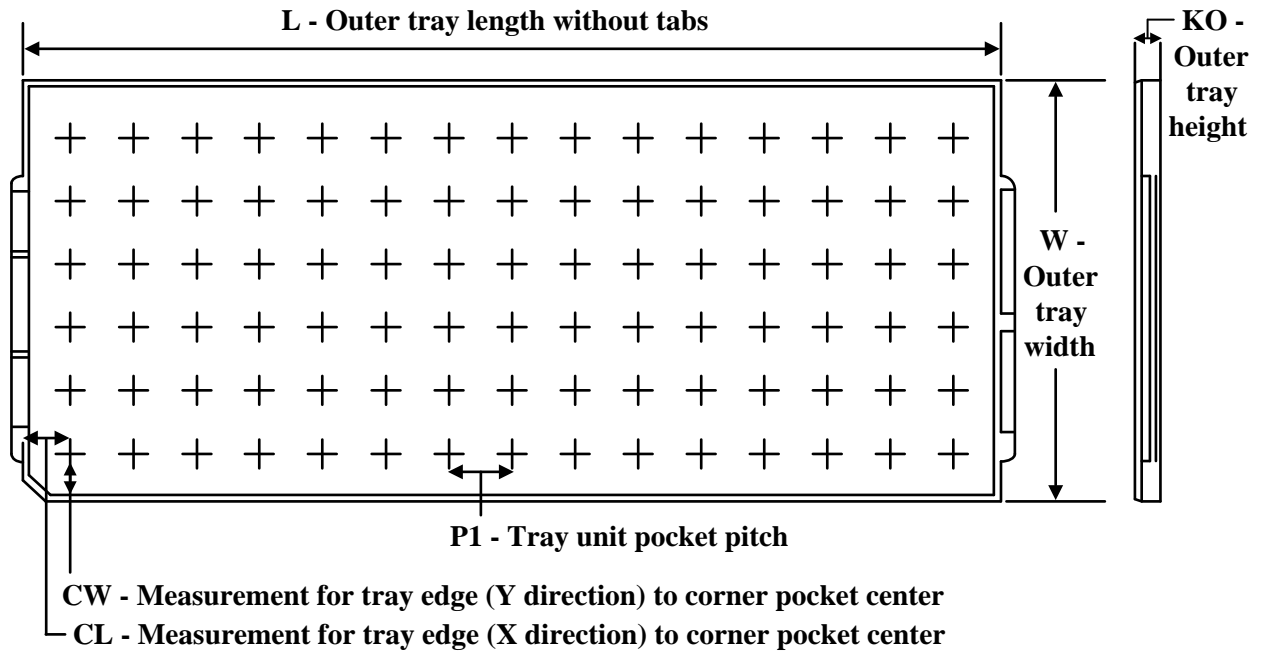

Chamfer on Tray corner indicates Pin 1 orientation of packed units.

\*All dimensions are nominal

| Device        | Package Name | Package Type | Pins | SPQ | Unit array matrix | Max temperature (°C) | L (mm) | W (mm) | K0 (µm) | P1 (mm) | CL (mm) | CW (mm) |
|---------------|--------------|--------------|------|-----|-------------------|----------------------|--------|--------|---------|---------|---------|---------|
| DAC3482IZAY   | ZAY          | NFBGA        | 196  | 160 | 8 x 20            | 150                  | 315    | 135.9  | 7620    | 15.4    | 11.2    | 19.65   |
| DAC3482IZAY.A | ZAY          | NFBGA        | 196  | 160 | 8 x 20            | 150                  | 315    | 135.9  | 7620    | 15.4    | 11.2    | 19.65   |