



TAPE AND REEL INFORMATION

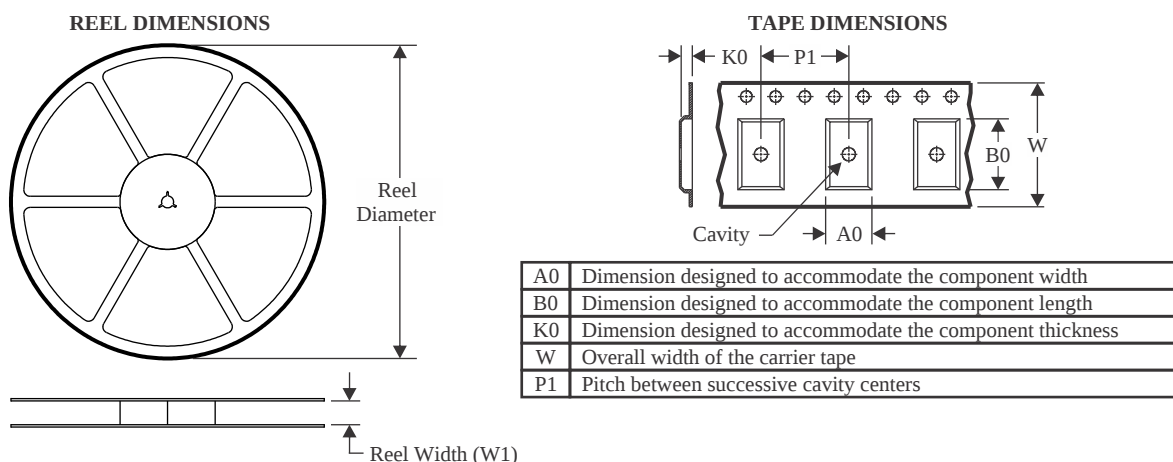

QUADRANT ASSIGNMENTS FOR PIN 1 ORIENTATION IN TAPE

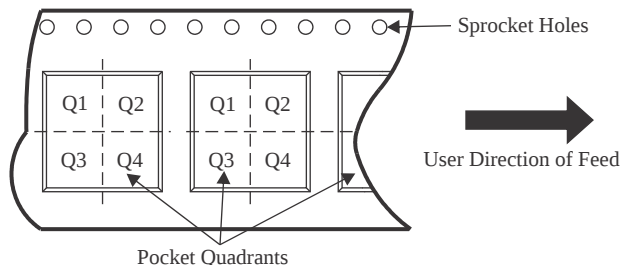

*All dimensions are nominal

Device	Package Type	Package Drawing	Pins	SPQ	Reel Diameter (mm)	Reel Width W1 (mm)	A0 (mm)	B0 (mm)	K0 (mm)	P1 (mm)	W (mm)	Pin1 Quadrant
TPS923652DMTR	VSON	DMT	14	3000	330.0	12.4	3.3	4.8	1.2	8.0	12.0	Q1
TPS923652DRRR	WSON	DRR	12	3000	330.0	12.4	3.3	3.3	1.1	8.0	12.0	Q2
TPS923652DYYR	SOT-23-THIN	DYY	14	3000	330.0	12.4	4.8	3.6	1.6	8.0	12.0	Q3
TPS923653DMTR	VSON	DMT	14	3000	330.0	12.4	3.3	4.8	1.2	8.0	12.0	Q1
TPS923653DRRR	WSON	DRR	12	3000	330.0	12.4	3.3	3.3	1.1	8.0	12.0	Q2
TPS923653DYYR	SOT-23-THIN	DYY	14	3000	330.0	12.4	4.8	3.6	1.6	8.0	12.0	Q3
TPS923654DMTR	VSON	DMT	14	3000	330.0	12.4	3.3	4.8	1.2	8.0	12.0	Q1
TPS923654DRRR	WSON	DRR	12	3000	330.0	12.4	3.3	3.3	1.1	8.0	12.0	Q2
TPS923654HMDMTR	VSON	DMT	14	3000	330.0	12.4	3.3	4.8	1.2	8.0	12.0	Q1
TPS923654MDMTR	VSON	DMT	14	3000	330.0	12.4	3.3	4.8	1.2	8.0	12.0	Q1
TPS923655DMTR	VSON	DMT	14	3000	330.0	12.4	3.3	4.8	1.2	8.0	12.0	Q1
TPS923655DRRR	WSON	DRR	12	3000	330.0	12.4	3.3	3.3	1.1	8.0	12.0	Q2
TPS923655HMDMTR	VSON	DMT	14	3000	330.0	12.4	3.3	4.8	1.2	8.0	12.0	Q1
TPS923655MDMTR	VSON	DMT	14	3000	330.0	12.4	3.3	4.8	1.2	8.0	12.0	Q1

TAPE AND REEL BOX DIMENSIONS



*All dimensions are nominal

Device	Package Type	Package Drawing	Pins	SPQ	Length (mm)	Width (mm)	Height (mm)
TPS923652DMTR	VSON	DMT	14	3000	367.0	367.0	35.0
TPS923652DRRR	WSON	DRR	12	3000	360.0	360.0	36.0
TPS923652DYYR	SOT-23-THIN	DYY	14	3000	336.6	336.6	31.8
TPS923653DMTR	VSON	DMT	14	3000	367.0	367.0	35.0
TPS923653DRRR	WSON	DRR	12	3000	360.0	360.0	36.0
TPS923653DYYR	SOT-23-THIN	DYY	14	3000	336.6	336.6	31.8
TPS923654DMTR	VSON	DMT	14	3000	367.0	367.0	35.0
TPS923654DRRR	WSON	DRR	12	3000	360.0	360.0	36.0
TPS923654HMDMTR	VSON	DMT	14	3000	367.0	367.0	35.0
TPS923654MDMTR	VSON	DMT	14	3000	367.0	367.0	35.0
TPS923655DMTR	VSON	DMT	14	3000	367.0	367.0	35.0
TPS923655DRRR	WSON	DRR	12	3000	360.0	360.0	36.0
TPS923655HMDMTR	VSON	DMT	14	3000	367.0	367.0	35.0
TPS923655MDMTR	VSON	DMT	14	3000	367.0	367.0	35.0